


Information on Components Used

Connector / Hood


MIL / MILFT / GLML / GRPMF



Female Connector	
Manufacturer	Misumi
Model Number	MILE-**-2.54-S
More Information	OP.49

Male Connector	
Manufacturer	Misumi
Model Number	MILE-**-2.54-P
More Information	OP.49


HIFS / MILSF / ZHMILSF / GRNM / GRNMF

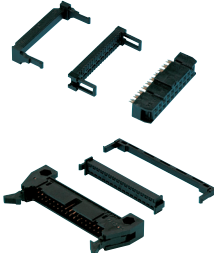

Female Connector	
Manufacturer	Hirose Electric Co., Ltd
Model Number	HIF3B**-**D-2.54**
Rated Current	1A
Rated Voltage	200 VAC
More Information	OP.48

Male Connector	
Manufacturer	Hirose Electric Co., Ltd
Model Number	HIF3B**-**PD-2.54R-MC
Rated Current	1A
Rated Voltage	200 VAC
More Information	OP.55

CHIFS / BHHIFS / BDHIFS / BDHIFSK

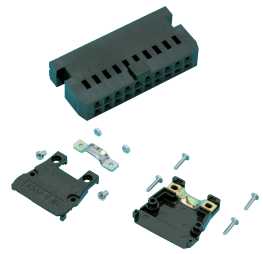


Female Connector	
Manufacturer	Hirose Electric Co., Ltd
Model Number	HIF3B**-**D-2.54C
Rated Current	1A
Rated Voltage	200 VAC
More Information	OP.45

Hood	
Manufacturer	Hirose Electric Co., Ltd
Model Number	HIF3**-**CV71
Rated Current	1A
Rated Voltage	200 VAC
More Information	OP.45


Crimp Terminal

SB




Y Type Crimp Terminals	
Manufacturer	Daido Solderless Terminal Mfg. Co.
Model Number	F0.3-3 Equivalent
Size	3.2mm
Outer Width	5.2mm
More Information	OP.468

Others




Y Type Crimp Terminals	
Manufacturer	Daido Solderless Terminal Mfg. Co.
Model Number	F1.25-3.5 Equivalent
Size	3.7mm
Outer Width	6.0mm
More Information	OP.468

WA / WB



Y Type Crimp Terminals	
Manufacturer	Daido Solderless Terminal Mfg. Co.
Model Number	F0.08-3 Equivalent
Size	3.2mm
Outer Width	5.2mm
More Information	OP.468




Round Type Crimp Terminals	
Manufacturer	Daido Solderless Terminal Mfg. Co.
Model Number	0.3-3 Equivalent
Size	3.2mm
Outer Width	5.2mm
More Information	OP.464

The Y type crimp terminals are for M3 screw terminal block. The crimp terminal used is changed according to the thickness of the cable used.


Multi-Core Cable

SB Cable




Manufacturer	Misumi
Model Number	SS30WS
Standard Acquired	AWM20276
Rated Temperature	80°C
Flame Retardance	VW-1SC
Bending Radius mm (Fixed Parts)	Finished Outer Diameter x 8
Bending Radius mm (Movable Parts)	—
More Information	OP.1339

KS Cable




Manufacturer	Misumi
Model Number	SS300SB
Standard Acquired	ULAWM2464
Rated Temperature	0 ~ 80°C
Flame Retardance	VW-1
Bending Radius mm (Fixed Parts)	Finished Outer Diameter x 6
Bending Radius mm (Movable Parts)	—
More Information	OP.1291

E Cable

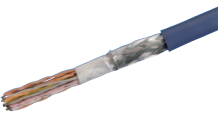

Manufacturer	Misumi
Model Number	NA2464
Standard Acquired	AWM2464
Rated Temperature	0 ~ 80°C
Flame Retardance	—
Bending Radius mm (Fixed Parts)	Finished Outer Diameter x 8
Bending Radius mm (Movable Parts)	—
More Information	OP.1293

RS Cable



Manufacturer	Misumi
Model Number	SS300RSB
Standard Acquired	AWM2464
Rated Temperature	0 ~ 80°C
Flame Retardance	VW-1
Bending Radius mm (Fixed Parts)	Finished Outer Diameter x 6
Bending Radius mm (Movable Parts)	Finished Outer Diameter x 6
More Information	OP.1505